

Technical data sheet

Cover for 45° bend A4

Item number: 7133988



Cover for 45° bend with pre-mounted turn buckles.
The cover can be used with fittings of all side heights.




A4 Stainless steel

2B Bright, treated

Master data

| | |
|---------------------|--------------------------------|
| Item number | 7133988 |
| Description 1 | 45° bend cover |
| Description 2 | with sash locks, for RB 45 300 |
| Manufacturer | OBO |
| Dimension | B300mm |
| Material | Stainless steel |
| Surface | Bright, treated |
| Surface standard | |
| Smallest sales unit | 1 |
| Unit of quantity | Piece |
| Weight | 55 kg |
| Weight unit | kg/100 pc. |

Dimensions

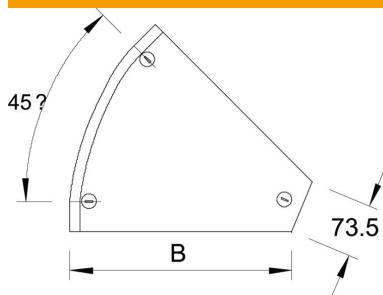

| | |
|-----------------|---------|
| Width | 300 mm |
| Width | 12 in |
| Height | 35 mm |
| Plate thickness | 0.04 in |
| Plate thickness | 1 mm |
| Dimension B | 300 mm |

Technical data sheet

Cover for 45° bend A4

Item number: 7133988



Technical data

| | |
|-------------------------------|------------|
| Bend (angle) | 45° |
| Fastening type | Sash lock |
| Maintain electrical functions | no |
| Suitable for mesh cable tray | no |
| Suitable for cable ladder | yes |
| Suitable for cable tray | yes |
| Change of direction | Horizontal |
| Rustproof steel, pickled | no |
| Hinged | no |