

Technical data sheet

Cover for 90° bend FT

Item number: 7131785



Cover for for 90° cable tray bend fitting, type RB 90 305 and 605.
Fixing under cable tray cover, no fastening material required.



St Steel

FT Hot-dip galvanised

Master data

Item number	7131785
Type	DFB 90 050 FT
Description 1	90° bend cover
Manufacturer	OBO
Dimension	B50mm
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	1
Unit of quantity	Piece
Weight	12 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,4995 kg CO2e / 1 Piece


Technical data sheet

Cover for 90° bend FT

Item number: 7131785



Dimensions

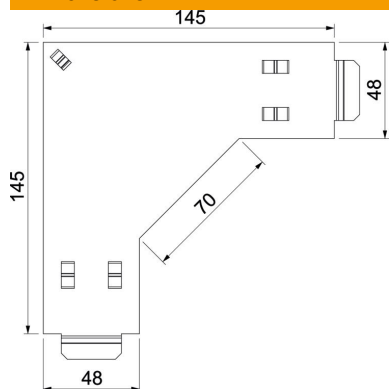

Length	160 mm
Width	50 mm
Plate thickness	1 mm
Dimension B	50 mm

Technical data

Bend (angle)	90°
Fastening type	On top
Maintain electrical functions	no
Suitable for mesh cable tray	no
Suitable for cable ladder	no
Suitable for cable tray	yes
Change of direction	Horizontal
Rustproof steel, pickled	no
Hinged	no