

Technical data sheet

Cover for 90° bend A4

Item number: 7134992



Cover for 90° bend with pre-mounted turn buckles.
The cover can be used with fittings of all side heights.




A4 Stainless steel

2B Bright, treated

Master data

Item number	7134992
Type	DFB 90 400 A4
Description 1	90° bend cover
Description 2	with turn-buckles, RB 90 400
Manufacturer	OBO
Dimension	B400mm
Material	Stainless steel 1.4571
Surface	Bright, treated
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	340 kg
Weight unit	kg/100 pc.

Dimensions

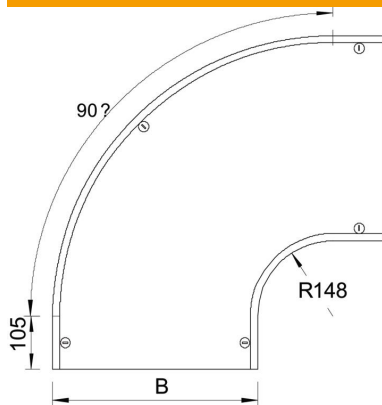

Width	400 mm
Width	16 in
Height	35 mm
Plate thickness	0.05 in
Plate thickness	1.25 mm
Dimension B	400 mm

Technical data sheet

Cover for 90° bend A4

Item number: 7134992



Technical data

Bend (angle)	90°
Fastening type	Sash lock
Maintain electrical functions	no
Suitable for mesh cable tray	no
Suitable for cable ladder	yes
Suitable for cable tray	yes
Change of direction	Horizontal
Rustproof steel, pickled	no
Hinged	no