


Technical data sheet

Cover for 90° bend DD

Item number: 7130600

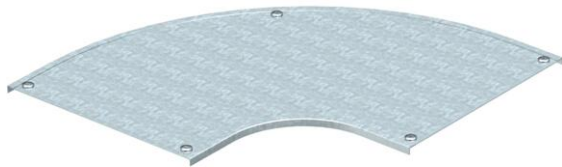

Cover for 90° bend with pre-mounted turn buckles.
The cover can be used with fittings of all side heights.




St Steel

DD Strip galvanised zinc/aluminium, Double Dip

Master data

Item number	7130600
Type	DFB 90 500 DD
Description 1	90° bend cover
Description 2	with turn-buckles, RB 90 500
Manufacturer	OBO
Dimension	B500mm
Material	Steel
Surface	Strip galvanised zinc/aluminium, Double Dip
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	535 kg
Weight unit	kg/100 pc.

Dimensions

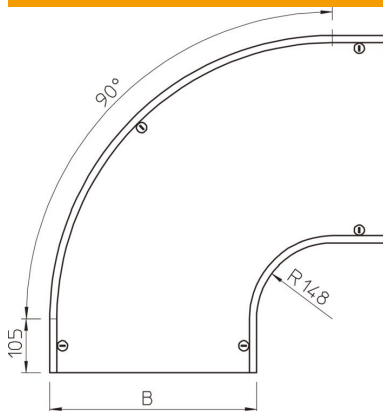

Width	500 mm
Width	20 in
Height	35 mm
Plate thickness	0.05 in
Plate thickness	1.25 mm
Dimension B	500 mm
Dimension H	15 mm
Dimension R	148 mm

Technical data sheet

Cover for 90° bend DD

Item number: 7130600



Technical data

Bend (angle)	90°
Number of turn buckles	5 St.
Fastening type	Sash lock
Maintain electrical functions	no
Suitable for mesh cable tray	no
Suitable for cable ladder	no
Suitable for cable tray	yes
Change of direction	Horizontal
Rustproof steel, pickled	no
Hinged	no
Permitted temperature range, max.	120 °C
Permitted temperature range, min.	-20 °C