


Technical data sheet

Cover for T branch piece DD

Item number: 7129319

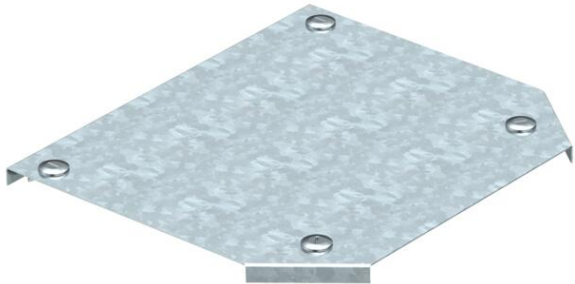

Cover for tee with pre-mounted turn buckle.
The cover can be used with fittings of all side heights.




- St** Steel
- DD** Strip galvanised zinc/aluminium, Double Dip

Master data

Item number	7129319
Type	DFT 100 DD
Description 1	Cover, T-branch piece
Description 2	with turn buckle, for RT 100
Manufacturer	OBO
Dimension	B100mm
Material	Steel
Surface	Strip galvanised zinc/aluminium, Double Dip
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	27 kg
Weight unit	kg/100 pc.

Dimensions

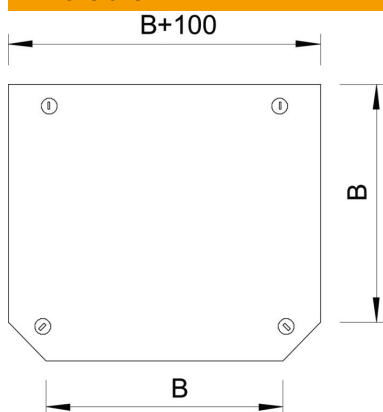

Width	100 mm
Width	4 in
Plate thickness	1 mm
Dimension B	100 mm
Dimension H	15 mm

Technical data sheet

Cover for T branch piece DD

Item number: 7129319



Technical data

Number of turn buckles	4 St.
Fastening type	Sash lock
Suitable for cable ladder	no
Suitable for cable tray	yes
Material thickness (inches)	0.04 in
Material thickness	1 mm
Rustproof steel, pickled	no
Wide-span version	no