


Technical data sheet

Cover for mesh cable tray, latchable A2

Item number: 6001866

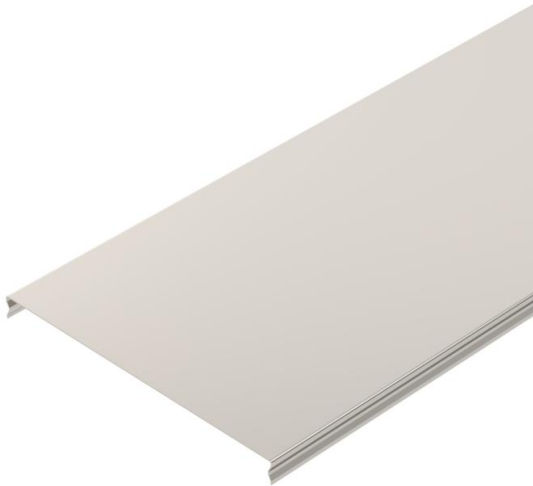

Lockable cover for mesh cable trays of type GR and GRM. Protects cables from damage, contamination and moisture from above. Suitable for the foodstuffs or chemicals industries.

With transverse bead from 400 mm width.

When using covers outdoors, additional measures against the influence of wind may need to be taken.



A2 Stainless steel

2B Bright, treated

Master data

Item number	6001866
Type	DGRR 200 A2
Description 1	Cover snapable
Description 2	for mesh cable tray
Available from	01.04.2019
Manufacturer	OBO
Dimension	200x3000
Colour	stainless steel
Material	Stainless steel
Surface	Bright, treated
Surface standard	
Smallest sales unit	3
Unit of quantity	Metre
Weight	141 kg
Weight unit	kg/100 m


Technical data sheet

Cover for mesh cable tray, latchable A2


Item number: 6001866



Dimensions

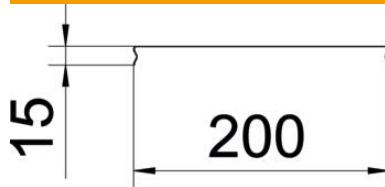

Length	3,000 mm
Width	198 mm
Width	7.8 in
Height	15 mm
Height	0.59 in
Plate thickness	0.8 mm
Dimension B	198 mm

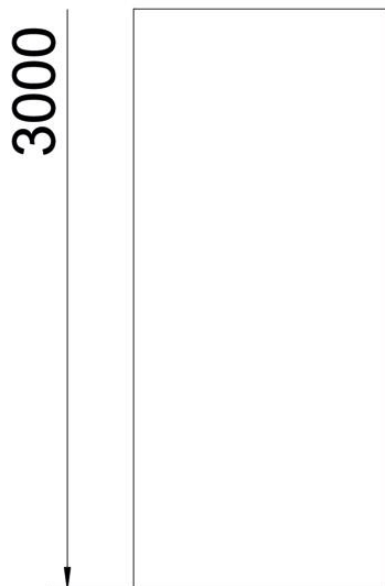

Technical data

Fastening type	Locking
Maintain electrical functions	no
Suitable for mesh cable tray	yes
Suitable for cable ladder	no
Suitable for cable tray	no
Rustproof steel, pickled	no