

# Technical data sheet

## Cover for mesh cable tray, latchable FT



Item number: 6001828



Lockable cover for mesh cable trays of type GR and GRM. Protects cables from damage, contamination and moisture from above. Suitable for industrial areas such as mechanical engineering.  
With transverse bead from 400 mm width.  
When using covers outdoors, additional measures against the influence of wind may need to be taken.



**St** Steel

**FT** Hot-dip galvanised

### Master data

Item number	6001828
Type	DGRR 300 FT
Description 1	Cover snapable
Description 2	for mesh cable tray
Available from	01.04.2019
Manufacturer	OBO
Dimension	300x3000
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	3
Unit of quantity	Metre
Weight	216.333 kg
Weight unit	kg/100 m
CO Footprint (GWP) Cradle-to-Gate	5,4634 kg COe / 1 Meter


# Technical data sheet

## Cover for mesh cable tray, latchable FT

Item number: 6001828



### Dimensions

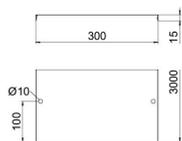

Length	3,000 mm
Width	298 mm
Width	11.73 in
Height	15 mm
Height	0.59 in
Plate thickness	0.75 mm
Dimension B	298 mm

### Technical data

Fastening type	Locking
Maintain electrical functions	no
Suitable for mesh cable tray	yes
Suitable for cable ladder	no
Suitable for cable tray	no
Rustproof steel, pickled	no