


# Technical data sheet

## Cover for mesh cable tray, latchable FT

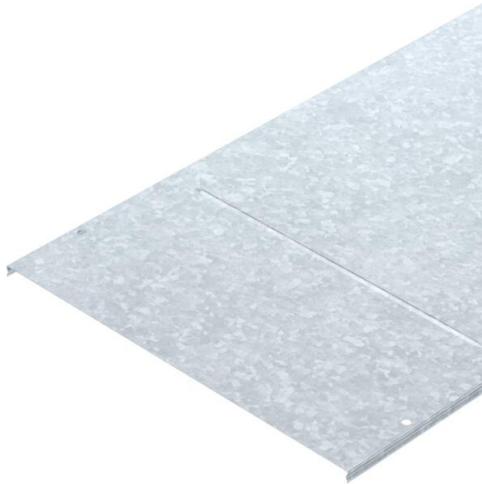

Item number: 6001832



Lockable cover for mesh cable trays of type GR and GRM. Protects cables from damage, contamination and moisture from above. Suitable for industrial areas such as mechanical engineering.  
With transverse bead from 400 mm width.  
When using covers outdoors, additional measures against the influence of wind may need to be taken.



**St** Steel

**FT** Hot-dip galvanised

### Master data

Item number	6001832
Type	DGRR 500 FT
Description 1	Cover snapable
Description 2	for mesh cable tray
Available from	01.04.2019
Manufacturer	OBO
Dimension	500x3000
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	3
Unit of quantity	Metre
Weight	349.667 kg
Weight unit	kg/100 m
CO Footprint (GWP) Cradle-to-Gate	10,3483 kg COe / 1 Meter


# Technical data sheet

## Cover for mesh cable tray, latchable FT

Item number: 6001832



### Dimensions

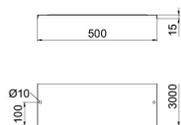

Length	3,000 mm
Width	498 mm
Width	19.61 in
Height	15 mm
Height	0.59 in
Plate thickness	0.75 mm
Dimension B	498 mm

### Technical data

Fastening type	Locking
Maintain electrical functions	no
Suitable for mesh cable tray	yes
Suitable for cable ladder	no
Suitable for cable tray	no
Rustproof steel, pickled	no