


# Technical data sheet

## Hexagonal nut ISO 4032

Item number: 3400379



Hexagonal nut to DIN 934 with metric thread.

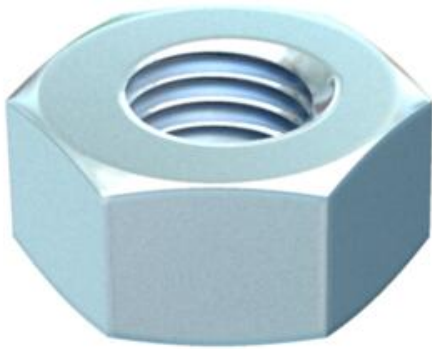

St

Steel

F

Hot galvanized

### Master data

|                                   |                         |
|-----------------------------------|-------------------------|
| Item number                       | 3400379                 |
| Type                              | DIN934 M12 F            |
| Description 1                     | Hexagonal nut           |
| Description 2                     | to DIN 934              |
| Manufacturer                      | OBO                     |
| Dimension                         | M12                     |
| Colour                            | zinc                    |
| Material                          | Steel                   |
| Surface                           | Hot galvanized          |
| Surface standard                  | DIN 267, Teil 10        |
| Smallest sales unit               | 100                     |
| Unit of quantity                  | Piece                   |
| Weight                            | 1.54 kg                 |
| Weight unit                       | kg/100 pc.              |
| CO Footprint (GWP) Cradle-to-Gate | 0,0434 kg COe / 1 Piece |

# Technical data sheet

## Hexagonal nut ISO 4032

Item number: 3400379



### Dimensions

|             |         |
|-------------|---------|
| Dimension d | 12 mm   |
| Dimension h | 10.8 mm |

### Technical data

|                  |              |
|------------------|--------------|
| Thread           | M12          |
| Thread metric    | 12           |
| Thread type      | Metric       |
| Halogen-free     | yes          |
| With flange      | no           |
| WAF              | 19           |
| Self-locking     | no           |
| Left thread      | no           |
| Thread, imperial | 1/2"         |
| Nut version      | Nut          |
| Screw system nut | Hexagon head |