


Technical data sheet

Cover, unperforated FT

Item number: 6052006



Unperforated cover for cable trays and cable ladders in indoor and outdoor areas, for the protection of the cables against damage and dirt. Fastening with cover clamp. When the cover is used under the impact of wind, suction or pressure, additional securing measures must be carried out.

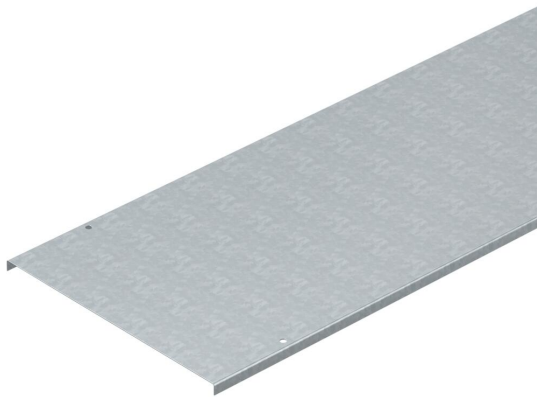

- St** Steel
- FT** Hot-dip galvanised

Master data	
Item number	6052006
Type	DRLU 300 FT
Description 1	Unperforated cover
Description 2	for cable tray and ladder
Manufacturer	OBO
Dimension	300x3000
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	3
Unit of quantity	Metre
Weight	281.333 kg
Weight unit	kg/100 m


Technical data sheet

Cover, unperforated FT

Item number: 6052006



Dimensions

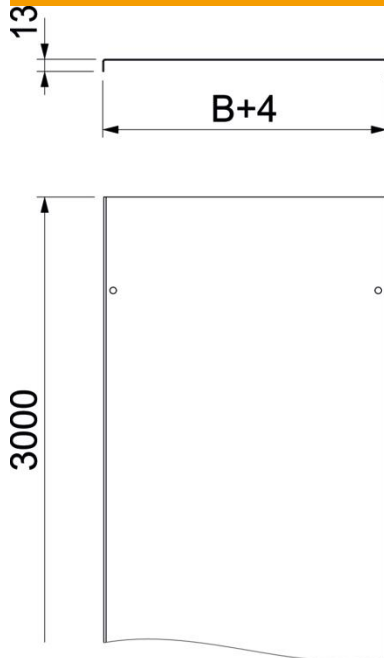

Length	3,000 mm
Width	300 mm
Plate thickness	0.7 mm
Dimension B	300 mm

Technical data

Fastening type	Cover clamp
Maintain electrical functions	no
Suitable for mesh cable tray	yes
Suitable for cable ladder	yes
Suitable for cable tray	yes
Rustproof steel, pickled	no