

Technical data sheet

Cover with turn buckle FT

Item number: 6051367



Cover for cable trays and cable ladders with three pairs of turn buckles.
Transverse bead from 500 mm width.
When using covers outdoors, additional measures against the influence of wind must be taken.



- St** Steel
- FT** Hot-dip galvanised

Master data

| | |
|-----------------------------------|---------------------------|
| Item number | 6051367 |
| Description 1 | Cover with turn buckle |
| Description 2 | for cable tray and ladder |
| Manufacturer | OBO |
| Dimension | 200x3000 |
| Colour | zinc |
| Material | Steel |
| Surface | Hot-dip galvanised |
| Surface standard | DIN EN ISO 1461 |
| Smallest sales unit | 3 |
| Unit of quantity | Metre |
| Weight | 202.67 kg |
| Weight unit | kg/100 m |
| CO Footprint (GWP) Cradle-to-Gate | 4,485 kg COe / 1 Meter |


Technical data sheet

Cover with turn buckle FT

Item number: 6051367



Dimensions

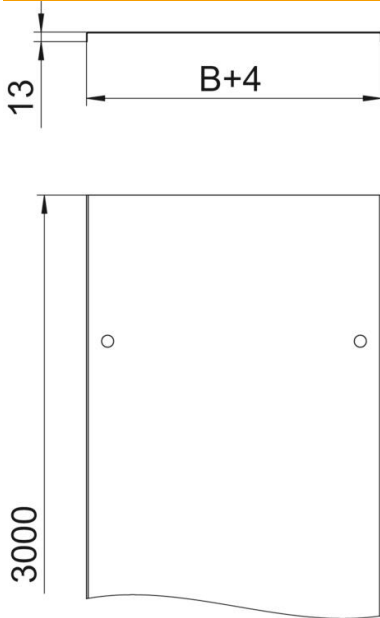

| | |
|-----------------|----------|
| Length | 3,000 mm |
| Length | 10 ft |
| Width | 200 mm |
| Width | 8 in |
| Height | 13 mm |
| Plate thickness | 0.04 in |
| Plate thickness | 1 mm |
| Dimension B | 200 mm |

Technical data

| | |
|-------------------------------|-----------|
| Fastening type | Sash lock |
| Maintain electrical functions | no |
| Suitable for mesh cable tray | no |
| Suitable for cable ladder | yes |
| Suitable for cable tray | yes |
| Rustproof steel, pickled | no |