


# Technical data sheet

## Insert plate FS

Item number: 6103332



Insert plate for use in cable ladders.  
For fastening in wide span cable ladders, use truss-head bolts with combination nut of type FR SB 6x30.

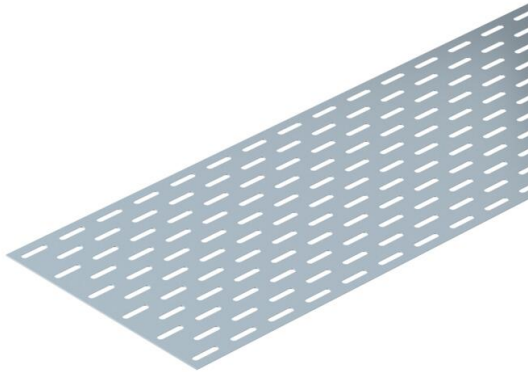

- St** Steel
- FS** Strip galvanized

### Master data

|                                    |                             |
|------------------------------------|-----------------------------|
| Item number                        | 6103332                     |
| Type                               | ELB-L 60 FS                 |
| Description 1                      | Insertion plate             |
| Description 2                      | perforated for cable ladder |
| Manufacturer                       | OBO                         |
| Dimension                          | 600x3000                    |
| Colour                             | zinc                        |
| Material                           | Steel                       |
| Surface                            | Strip galvanized            |
| Surface standard                   | DIN EN 10346                |
| Smallest sales unit                | 3                           |
| Unit of quantity                   | Metre                       |
| Weight                             | 285.07 kg                   |
| Weight unit                        | kg/100 m                    |
| CO2 Footprint (GWP) Cradle-to-Gate | 7,3316 kg CO2e / 1 Meter    |


# Technical data sheet

## Insert plate FS

Item number: 6103332



### Dimensions

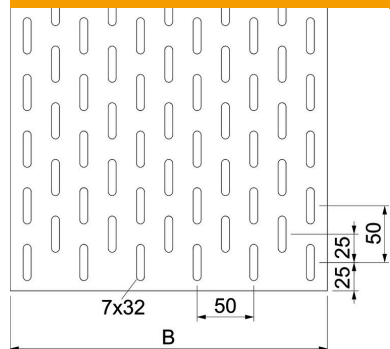

|             |          |
|-------------|----------|
| Length      | 3,000 mm |
| Width       | 600 mm   |
| Height      | 45 mm    |
| Dimension B | 600 mm   |

### Technical data

|                    |      |
|--------------------|------|
| Material thickness | 1 mm |
|--------------------|------|