

Technical data sheet

Screw-in beam clamp, with thread

Item number: 1488090



With thread.

Max. tightening torque: 21 Nm



TG

Cast iron

Master data		
Item number	1488090	
Description 1	Carrier screw clamp	
Description 2	with female thread M12	
Manufacturer	OBO	
Dimension	0-26mm	
Material	Cast iron	
Smallest sales unit	25	
Unit of quantity	Piece	
Weight	22 kg	
Weight unit	kg/100 pc.	


Technical data sheet

Screw-in beam clamp, with thread

Item number: 1488090



Dimensions

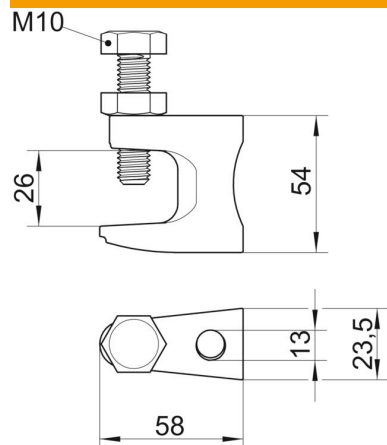

Length	58 mm
Width	23.5 mm
Height	54 mm
Dimension B	23.5 mm
Dimension F	26 mm
Dimension G (mm)	M10
Dimension H	54 mm
Dimension L	58 mm

Technical data

Connection type/component	Thread
Fastening type	Bolts
Breaking load	3.5 kN
Flange thickness F max.	26 mm
Flange thickness F min.	0 mm
Suitable for metric threaded rod	12
Thread metric	12
Max. Tightening torque	21 Nm
Hinge, adjustable	no
Hinged	no