

Technical data sheet

Magic straight connector A2

Item number: 6065936



Magic straight connector for direct and screwless joining of Magic fittings with a side height of 110 mm.

The straight connector is equipped with four brackets and can also be used for the direct connection with a cut cable tray with only two brackets mounted to one side. To join a cut cable tray with a fitting, an additional Magic straight connector set is needed.

The fitting connector is compatible with cable tray types MKSM, MKSMU, SKSM and SKSMU.



A2 Stainless steel

2B Bright, treated

Master data

Item number	6065936
Type	FVM 130 A2
Description 1	Straight connector
Description 2	with quick connector
Manufacturer	OBO
Dimension	110x300
Material	Stainless steel 1.4301
Surface	Bright, treated
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	67.7 kg
Weight unit	kg/100 pc.



Technical data sheet

Magic straight connector A2

Item number: 6065936



Dimensions

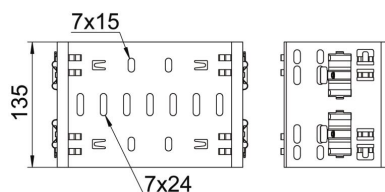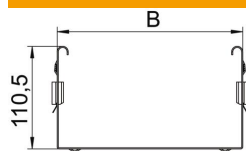

Length	135 mm
Width	300 mm
Height	110 mm
Plate thickness	1.25 mm
Dimension B	300 mm

Technical data

Version for	Straight connector
Maintain electrical functions	no
Suitable for mesh cable tray	no
Suitable for cable ladder	no
Suitable for cable tray	yes
Suitable for cable tray system height	110 mm
Adjustable connector, horizontal	no
Articulated connector, vertical	no
Rustproof steel, pickled	no
Connection type	Screwless connector