

# Technical data sheet

## Magic straight connector A2



Item number: 6065738

Magic straight connector for direct and screwless joining of Magic fittings with a side height of 60 mm.

The straight connector is equipped with four brackets and can also be used for the direct connection with a cut cable tray with only two brackets mounted to one side. To join a cut cable tray with a fitting, an additional Magic straight connector set is needed.

The fitting connector is compatible with cable tray types RKSM, MKSM, MKSMU, SKSM and SKSMU.



**A2** Stainless steel

**2B** Bright, treated

### Master data

Item number	6065738
Type	FVM 640 A2
Description 1	Straight connector
Description 2	with quick connector
Manufacturer	OBO
Dimension	60x400
Colour	stainless steel
Material	Stainless steel 1.4301
Surface	Bright, treated
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	69.4 kg
Weight unit	kg/100 pc.


# Technical data sheet

## Magic straight connector A2

Item number: 6065738



### Dimensions

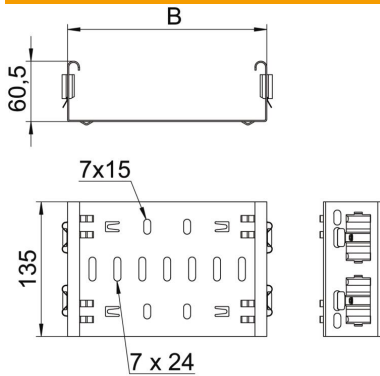

Length	135 mm
Width	400 mm
Height	60 mm
Plate thickness	1.25 mm
Dimension B	400 mm

### Technical data

Version for	Straight connector
Maintain electrical functions	no
Suitable for mesh cable tray	no
Suitable for cable ladder	no
Suitable for cable tray	yes
Suitable for cable tray system height	60 mm
Adjustable connector, horizontal	no
Articulated connector, vertical	no
Rustproof steel, pickled	no
Connection type	Screwless connector