

Technical data sheet

Joint cover, trunking height 70 mm

Item number: 6279764



Joint cover to hide sawn trunking joint edges.




St Steel

Master data

Item number	6279764
Description 1	Joint cover
Manufacturer	OBO
Dimension	70x130x30mm
Colour	Pure white; RAL 9010
Material	Steel
Smallest sales unit	1
Unit of quantity	Piece
Weight	5.2 kg
Weight unit	kg/100 pc.

Dimensions

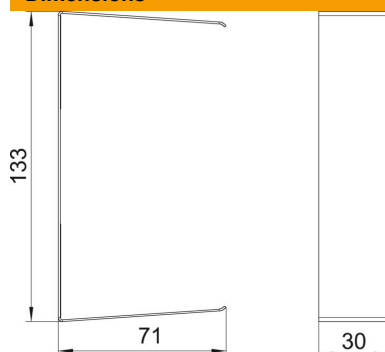

Length	30 mm
Width	133 mm
Height	71 mm

Technical data sheet

Joint cover, trunking height 70 mm

Item number: 6279764



Technical data

Version for	Trunking cut cover
Fastening type	Self-adhesive
Shape	Universal
for duct dimension	70x130
for duct width	130 mm
for trunking height	70 mm
Halogen-free	yes
Duct height, min.	70 mm
Trunking depth	70 mm
Cover width	76.5 mm
Protection rating	IP30
Protection rating IK code	IK10
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-25 °C