

Technical data sheet

External corner, asymmetrical, for device installation trunking Rapid 80 type GA-A70170

Item number: 6279413



External corner for changing the direction of the Rapid 80 GA aluminium device installation trunking.
The visible surfaces of the fittings are laminated. The cover must be ordered separately.



Alu Aluminium

EL Anodised

Master data

Item number	6279413
Type	GA-AA70170EL
Description 1	External corner
Description 2	asymmetrical
Manufacturer	OBO
Dimension	70x170x300
Colour	aluminium
Material	Aluminium
Surface	Anodised
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	202.2 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	26,5951 kg CO2e / 1 Piece

Technical data sheet

External corner, asymmetrical, for device installation trunking Rapid 80 type GA-A70170


Item number: 6279413



Dimensions



Length	300 mm
Width	170 mm
Height	70 mm

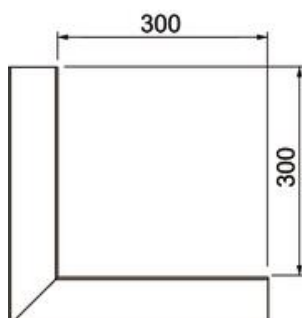

Technical data

Number of covers	1
Version for	Base
for duct width	170 mm
for trunking height	70 mm
Halogen-free	yes
Cable retaining clip	no
Duct connector	no
Cover mounting type	Internal
Mounting perforation in base	no
Cover width	76.5 mm
Protection rating	IP30
Protective film	yes
Protection rating IK code	IK10
Symmetrical	no
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-25 °C
Angle range, min.	90 mm