

# Technical data sheet

External corner, asymmetrical, for device installation trunking Rapid 80 type GA-A90170

Item number: 6279510



External corner for changing the direction of the Rapid 80 GA aluminium device installation trunking.  
The visible surfaces of the fittings are laminated. The cover must be ordered separately.



Alu Aluminium

## Master data

Item number	6279510
Type	GA-AA90170RW
Description 1	External corner
Description 2	asymmetrical
Manufacturer	OBO
Dimension	90x170x300
Colour	Pure white; RAL 9010
Material	Aluminium
Smallest sales unit	1
Unit of quantity	Piece
Weight	229.2 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	30,8204 kg CO2e / 1 Piece


# Technical data sheet

External corner, asymmetrical, for device installation trunking Rapid 80 type GA-A90170


Item number: 6279510



## Dimensions

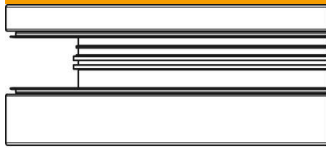

Length	300 mm
Width	170 mm
Height	90 mm

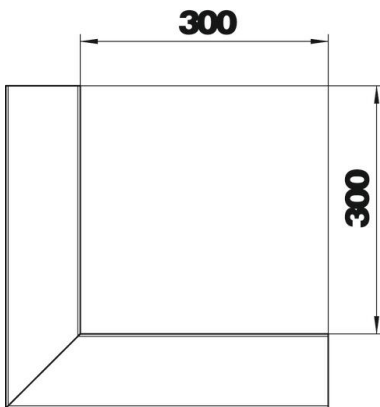

## Technical data

Number of covers	1
Version for	Base
for duct width	170 mm
for trunking height	90 mm
Halogen-free	yes
Cable retaining clip	no
Duct connector	no
Cover mounting type	Internal
Mounting perforation in base	no
Cover width	76.5 mm
Protection rating	IP30
Protective film	yes
Protection rating IK code	IK10
Symmetrical	no
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-25 °C
Angle range, min.	90 mm