

# Technical data sheet

Flat angle, asymmetrical, falling, for device installation  
trunking Rapid 80 type GA-A70170  
Item number: 6279433



Flat angle, falling, for changing the direction of the Rapid 80 GA aluminium device installation trunking.

The visible surfaces of the fittings are laminated. The cover must be ordered separately.



**Alu** Aluminium

**EL** Anodised

## Master data

Item number	6279433
Type	GA-AFF70170EL
Description 1	Flat angle
Description 2	asymmetrical falling
Manufacturer	OBO
Dimension	70x170x300
Colour	aluminium
Material	Aluminium
Surface	Anodised
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	132.6 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	22,2912 kg CO2e / 1 Piece


# Technical data sheet

Flat angle, asymmetrical, falling, for device installation  
trunking Rapid 80 type GA-A70170

Item number: 6279433



## Dimensions

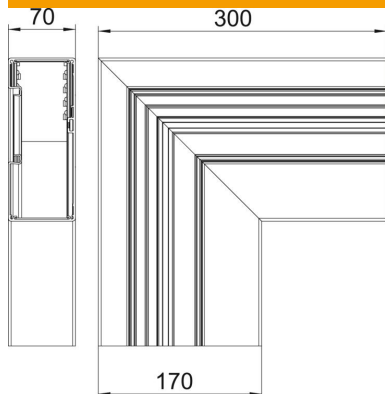

Length	300 mm
Width	170 mm
Height	70 mm

## Technical data

Number of covers	1
Version for	Base
for duct width	170 mm
for trunking height	70 mm
Halogen-free	yes
Cable retaining clip	no
Duct connector	no
Cover mounting type	Internal
Mounting perforation in base	no
Cover width	76.5 mm
Change of direction	Vertical, falling
Protection rating	IP30
Protective film	yes
Protection rating IK code	IK10
Symmetrical	no
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-25 °C
Angle range, min.	90 mm