

Technical data sheet

Flat angle, asymmetrical, falling, for device installation
trunking Rapid 80 type GA-90170
Item number: 6279530



Flat angle, falling, for changing the direction of the Rapid 80 GA aluminium device installation trunking.
The visible surfaces of the fittings are laminated. The cover must be ordered separately.



Alu Aluminium

Master data


Item number	6279530
Type	GA-AFF90170RW
Description 1	Flat angle
Description 2	asymmetrical falling
Manufacturer	OBO
Dimension	90x170x300
Colour	Pure white; RAL 9010
Material	Aluminium
Smallest sales unit	1
Unit of quantity	Piece
Weight	149.4 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	24,1754 kg CO2e / 1 Piece

Technical data sheet

Flat angle, asymmetrical, falling, for device installation
trunking Rapid 80 type GA-90170
Item number: 6279530



Dimensions

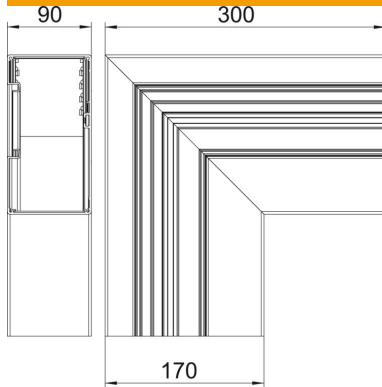

Length	300 mm
Width	170 mm
Height	90 mm

Technical data

Number of covers	1
Version for	Base
for duct width	170 mm
for trunking height	90 mm
Halogen-free	yes
Cable retaining clip	no
Duct connector	no
Cover mounting type	Internal
Mounting perforation in base	no
Cover width	76.5 mm
Change of direction	Vertical, falling
Protection rating	IP30
Protective film	yes
Protection rating IK code	IK10
Symmetrical	no
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-25 °C
Angle range, min.	90 mm