

Technical data sheet

Internal corner, asymmetrical, for device installation trunking Rapid 80 type GA-A90170

Item number: 6279543



Internal corner for changing the direction of the Rapid 80 GA aluminium device installation trunking.
The visible surfaces of the fittings are laminated.



- Alu** Aluminium
- EL** Anodised

Master data

Item number	6279543
Type	GA-AI90170EL
Description 1	Internal corner
Description 2	asymmetrical
Manufacturer	OBO
Dimension	90x170x300
Colour	aluminium
Material	Aluminium
Surface	Anodised
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	186.4 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	26,0847 kg CO2e / 1 Piece


Technical data sheet

Internal corner, asymmetrical, for device installation trunking Rapid 80 type GA-A90170


Item number: 6279543



Dimensions

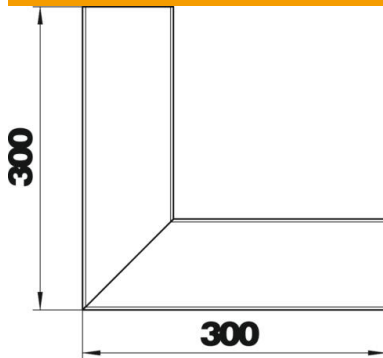

Length	300 mm
Width	170 mm
Height	90 mm

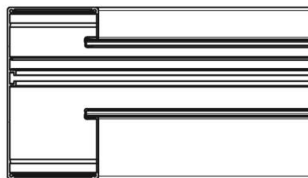

Technical data

Number of covers	1
Version for	Base
Shape	Asymmetrical
for duct dimension	90 x 170 mm
for duct width	170 mm
for trunking height	90 mm
Halogen-free	yes
Cable retaining clip	no
Duct connector	no
Cover mounting type	Internal
Mounting perforation in base	no
Cover width	76.5 mm
Protection rating	IP30
Protective film	yes
Protection rating IK code	IK10
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-25 °C
Angle range, min.	90 mm