

Technical data sheet

T piece, asymmetrical, for device installation trunking Rapid 80 type GA-A70170
Item number: 6279460



T piece for branches of Rapid 80 GA aluminium device installation trunking. The visible surfaces of the fittings are laminated.



Alu Aluminium

Master data

Item number	6279460
Type	GA-AT70170RW
Description 1	T piece
Description 2	asymmetrical
Manufacturer	OBO
Dimension	70x170x500
Colour	Pure white; RAL 9010
Material	Aluminium
Smallest sales unit	1
Unit of quantity	Piece
Weight	127.6 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	16,9433 kg CO2e / 1 Piece

 
Technical data sheet

T piece, asymmetrical, for device installation trunking Rapid 80 type GA-A70170


Item number: 6279460



Dimensions



Length	500 mm
Width	170 mm
Height	70 mm

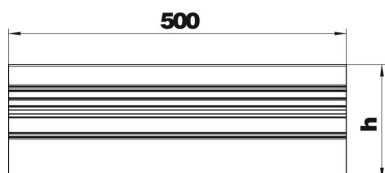

Technical data

Number of covers	1
Version for	Base
for duct width	170 mm
for trunking height	70 mm
Halogen-free	yes
Cable retaining clip	no
Duct connector	no
Cover mounting type	Internal
Mounting perforation in base	no
Cover width	76.5 mm
Protection rating	IP30
Protective film	yes
Protection rating IK code	IK10
Symmetrical	no
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-25 °C