


Technical data sheet

T piece, asymmetrical, for device installation trunking Rapid 80 type GA-A90170
Item number: 6279563

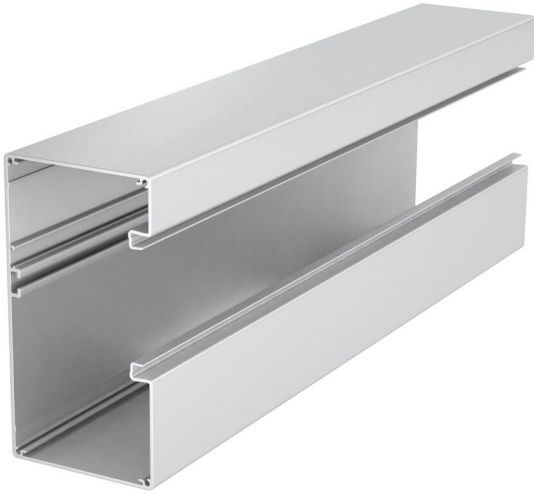

T piece for branches of Rapid 80 GA aluminium device installation trunking.
The visible surfaces of the fittings are laminated.



- Alu** Aluminium
- EL** Anodised

Master data

Item number	6279563
Type	GA-AT90170EL
Description 1	T piece
Description 2	asymmetrical
Manufacturer	OBO
Dimension	90x170x500
Colour	aluminium
Material	Aluminium
Surface	Anodised
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	136.6 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	18,3552 kg CO2e / 1 Piece

 
Technical data sheet

T piece, asymmetrical, for device installation trunking Rapid 80 type GA-A90170


Item number: 6279563



Dimensions



Length	500 mm
Width	170 mm
Height	90 mm

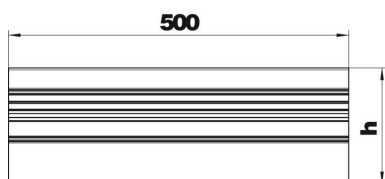

Technical data

Number of covers	1
Version for	Base
for duct width	170 mm
for trunking height	90 mm
Halogen-free	yes
Cable retaining clip	no
Duct connector	no
Cover mounting type	Internal
Mounting perforation in base	no
Cover width	76.5 mm
Protection rating	IP30
Protective film	yes
Protection rating IK code	IK10
Symmetrical	no
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-25 °C