

Technical data sheet

T piece, asymmetrical, for device installation trunking Rapid 80 type GA-A90170
Item number: 6279560



T piece for branches of Rapid 80 GA aluminium device installation trunking.
The visible surfaces of the fittings are laminated.



Alu Aluminium

Master data

 
| | |
|------------------------------------|---------------------------|
| Item number | 6279560 |
| Type | GA-AT90170RW |
| Description 1 | T piece |
| Description 2 | asymmetrical |
| Manufacturer | OBO |
| Dimension | 90x170x500 |
| Colour | Pure white; RAL 9010 |
| Material | Aluminium |
| Smallest sales unit | 1 |
| Unit of quantity | Piece |
| Weight | 136.6 kg |
| Weight unit | kg/100 pc. |
| CO2 Footprint (GWP) Cradle-to-Gate | 18,3552 kg CO2e / 1 Piece |

Technical data sheet


T piece, asymmetrical, for device installation trunking Rapid 80 type GA-A90170
Item number: 6279560



Dimensions



| | |
|--------|--------|
| Length | 500 mm |
| Width | 170 mm |
| Height | 90 mm |

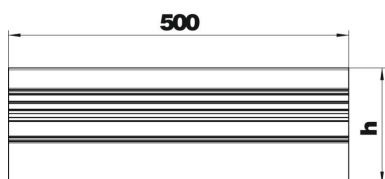

Technical data

| | |
|-----------------------------------|----------|
| Number of covers | 1 |
| Version for | Base |
| for duct width | 170 mm |
| for trunking height | 90 mm |
| Halogen-free | yes |
| Cable retaining clip | no |
| Duct connector | no |
| Cover mounting type | Internal |
| Mounting perforation in base | no |
| Cover width | 76.5 mm |
| Protection rating | IP30 |
| Protective film | yes |
| Protection rating IK code | IK10 |
| Symmetrical | no |
| Permitted temperature range, max. | 60 °C |
| Permitted temperature range, min. | -25 °C |