

Technical data sheet

External corner, symmetrical, for device installation trunking Rapid 80 type GA-D90210
Item number: 6279610



External corner for changing the direction of the Rapid 80 GA aluminium device installation trunking.
The visible surfaces of the fittings are laminated. The cover must be ordered separately.



Alu Aluminium

Master data

Item number	6279610
Type	GA-DA90210RW
Description 1	External corner
Description 2	2 compartments
Manufacturer	OBO
Dimension	90x210x300
Colour	Pure white; RAL 9010
Material	Aluminium
Smallest sales unit	1
Unit of quantity	Piece
Weight	291 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	41,1517 kg CO2e / 1 Piece

Technical data sheet


External corner, symmetrical, for device installation trunking Rapid 80 type GA-D90210
Item number: 6279610



Dimensions



Length	300 mm
Width	210 mm
Height	90 mm

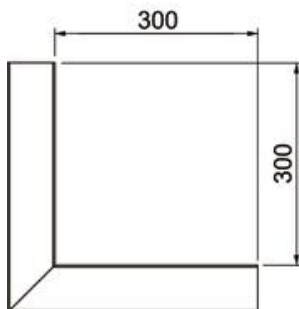

Technical data

Number of covers	2
Version for	Base
for duct width	210 mm
for trunking height	90 mm
Halogen-free	yes
Cable retaining clip	no
Duct connector	no
Cover mounting type	Internal
Mounting perforation in base	no
Cover width	76.5 mm
Cover width 2	76.5 mm
Protection rating	IP30
Protective film	yes
Protection rating IK code	IK10
Symmetrical	yes
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-25 °C
Angle range, min.	90 mm