

Technical data sheet

Flat angle, symmetrical, for device installation trunking Rapid 80 type GA-D90210

Item number: 6279623



Flat angle for changing the direction of the Rapid 80 GA aluminium device installation trunking.

The visible surfaces of the fittings are laminated. The cover must be ordered separately.



Alu Aluminium

EL Anodised

Master data

Item number	6279623
Type	GA-DF90210EL
Description 1	Flat angle
Description 2	2 compartments
Manufacturer	OBO
Dimension	90x210x300
Colour	aluminium
Material	Aluminium
Surface	Anodised
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	184.8 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	32,3186 kg CO2e / 1 Piece


Technical data sheet

Flat angle, symmetrical, for device installation trunking Rapid 80 type GA-D90210

Item number: 6279623



Dimensions

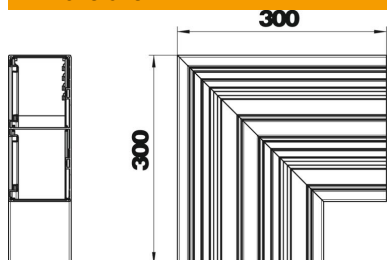

Length	300 mm
Width	210 mm
Height	90 mm

Technical data

Number of covers	2
Version for	Base
for duct width	210 mm
for trunking height	90 mm
Halogen-free	yes
Cable retaining clip	no
Duct connector	no
Cover mounting type	Internal
Mounting perforation in base	no
Cover width	76.5 mm
Cover width 2	76.5 mm
Change of direction	Vertical, rising/falling
Protection rating	IP30
Protective film	yes
Protection rating IK code	IK10
Symmetrical	yes
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-25 °C
Angle range, min.	90 mm