

# Technical data sheet

Internal corner, symmetrical, for device installation trunking Rapid 80 type GA-D90210

Item number: 6279643



Internal corner for changing the direction of the Rapid 80 GA aluminium device installation trunking.  
The visible surfaces of the fittings are laminated.



Alu	Aluminium
EL	Anodised

## Master data

Item number	6279643
Type	GA-DI90210EL
Description 1	Internal corner
Description 2	2 compartments
Manufacturer	OBO
Dimension	90x210x300
Colour	aluminium
Material	Aluminium
Surface	Anodised
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	237.2 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	34,7308 kg CO2e / 1 Piece


# Technical data sheet

Internal corner, symmetrical, for device installation trunking Rapid 80 type GA-D90210

Item number: 6279643



## Dimensions

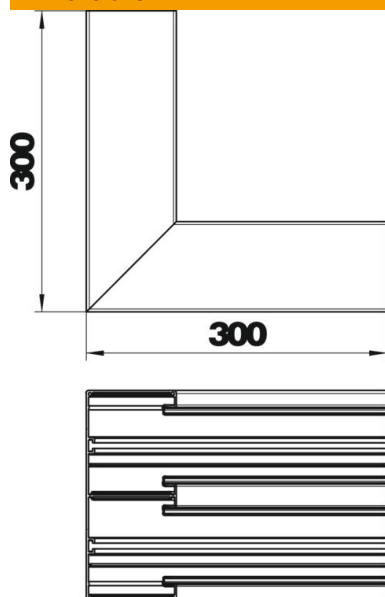

Length	300 mm
Width	210 mm
Height	90 mm

## Technical data

Number of covers	2
Version for	Base
Shape	Symmetrical
for duct dimension	90 x 210 mm
for duct width	210 mm
for trunking height	90 mm
Halogen-free	yes
Cable retaining clip	no
Duct connector	no
Cover mounting type	Internal
Mounting perforation in base	no
Cover width	76.5 mm
Cover width 2	76.5 mm
Protection rating	IP30
Protective film	yes
Protection rating IK code	IK10
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-25 °C
Angle range, min.	90 mm