

Technical data sheet

Internal corner, symmetrical, for device installation trunking Rapid 80 type GA-D90210

Item number: 6279640



Internal corner for changing the direction of the Rapid 80 GA aluminium device installation trunking.
The visible surfaces of the fittings are laminated.



Alu Aluminium

Master data

Item number	6279640
Type	GA-DI90210RW
Description 1	Internal corner
Description 2	2 compartments
Manufacturer	OBO
Dimension	90x210x300
Colour	Pure white; RAL 9010
Material	Aluminium
Smallest sales unit	1
Unit of quantity	Piece
Weight	237.2 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	34,538 kg CO2e / 1 Piece


Technical data sheet

Internal corner, symmetrical, for device installation trunking Rapid 80 type GA-D90210

Item number: 6279640



Dimensions

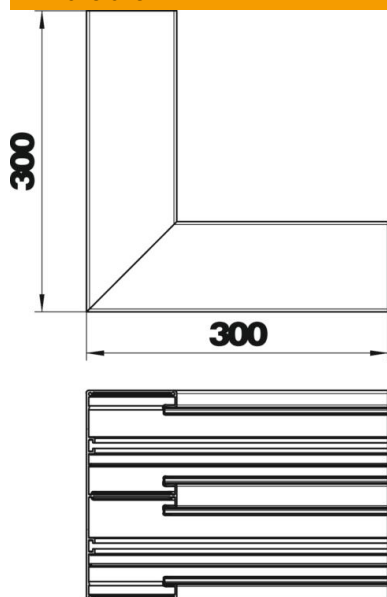

Length	300 mm
Width	210 mm
Height	90 mm

Technical data

Number of covers	2
Version for	Base
Shape	Symmetrical
for duct dimension	90 x 210 mm
for duct width	210 mm
for trunking height	90 mm
Halogen-free	yes
Cable retaining clip	no
Duct connector	no
Cover mounting type	Internal
Mounting perforation in base	no
Cover width	76.5 mm
Cover width 2	76.5 mm
Protection rating	IP30
Protective film	yes
Protection rating IK code	IK10
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-25 °C
Angle range, min.	90 mm