

Technical data sheet

T piece, symmetrical, for device installation trunking Rapid 80 type GA-D90210

Item number: 6279663



T piece for branches of Rapid 80 GA aluminium device installation trunking. The visible surfaces of the fittings are laminated.



- Alu** Aluminium
- EL** Anodised

Master data

 
Item number	6279663
Type	GA-DT90210EL
Description 1	T piece
Description 2	2 compartments
Manufacturer	OBO
Dimension	90x210x500
Colour	aluminium
Material	Aluminium
Surface	Anodised
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	177.4 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	24,3593 kg CO2e / 1 Piece

Technical data sheet


T piece, symmetrical, for device installation trunking Rapid
80 type GA-D90210
Item number: 6279663



Dimensions



Length	500 mm
Width	210 mm
Height	90 mm

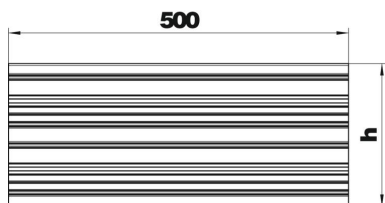

Technical data

Number of covers	2
Version for	Base
for duct width	210 mm
for trunking height	90 mm
Halogen-free	yes
Cable retaining clip	no
Duct connector	no
Cover mounting type	Internal
Mounting perforation in base	no
Cover width	76.5 mm
Cover width 2	76.5 mm
Protection rating	IP30
Protective film	yes
Protection rating IK code	IK10
Symmetrical	yes
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-25 °C