

Technical data sheet

End piece, for device installation trunking Rapid 80 type
GA-70110

Item number: 6279273



End piece for tidy closure of the Rapid 80 GA device installation trunking in aluminium.



- Alu** Aluminium
- EL** Anodised

Master data

| | |
|------------------------------------|--------------------------|
| Item number | 6279273 |
| Type | GA-E70110EL |
| Description 1 | End piece |
| Manufacturer | OBO |
| Dimension | 70x110x37 |
| Colour | aluminium |
| Material | Aluminium |
| Surface | Anodised |
| Surface standard | |
| Smallest sales unit | 1 |
| Unit of quantity | Piece |
| Weight | 10.8 kg |
| Weight unit | kg/100 pc. |
| CO2 Footprint (GWP) Cradle-to-Gate | 1,1922 kg CO2e / 1 Piece |


Technical data sheet

End piece, for device installation trunking Rapid 80 type
GA-70110

Item number: 6279273



Dimensions

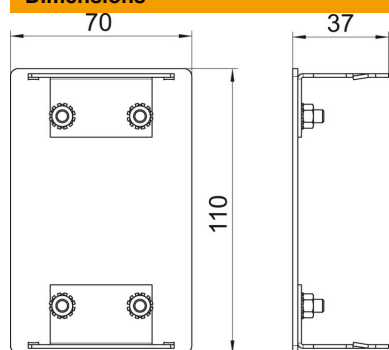

| | |
|--------|--------|
| Length | 37 mm |
| Width | 110 mm |
| Height | 70 mm |

Technical data

| | |
|-----------------------------------|-------------|
| Version for | Symmetrical |
| Fastening type | Lockable |
| for duct width | 110 mm |
| for trunking height | 70 mm |
| Suitable for | Left/right |
| Halogen-free | yes |
| Cut lamination | no |
| Protection rating | IP30 |
| Protective film | yes |
| Protection rating IK code | IK10 |
| Permitted temperature range, max. | 60 °C |
| Permitted temperature range, min. | -25 °C |