

Technical data sheet

End piece, for device installation trunking Rapid 80 type
GA-70110
Item number: 6279270



End piece for tidy closure of the Rapid 80 GA device installation trunking in aluminium.



Alu Aluminium

Master data


Item number	6279270
Type	GA-E70110RW
Description 1	End piece
Manufacturer	OBO
Dimension	70x110x37
Colour	Pure white; RAL 9010
Material	Aluminium
Smallest sales unit	1
Unit of quantity	Piece
Weight	11.2 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	1,2367 kg CO2e / 1 Piece

Technical data sheet

End piece, for device installation trunking Rapid 80 type
GA-70110
Item number: 6279270



Dimensions

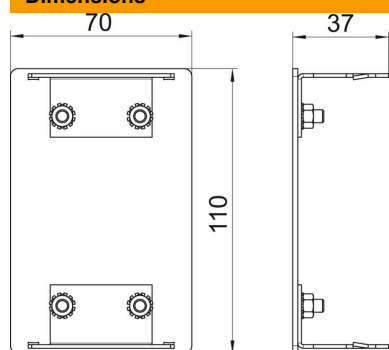

Length	37 mm
Width	110 mm
Height	70 mm

Technical data

Version for	Symmetrical
Fastening type	Lockable
for duct width	110 mm
for trunking height	70 mm
Suitable for	Left/right
Halogen-free	yes
Cut lamination	no
Protection rating	IP30
Protective film	yes
Protection rating IK code	IK10
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-25 °C