

# Technical data sheet

End piece, for device installation trunking Rapid 80 type  
GA-90130  
Item number: 6276973



End piece for tidy closure of the Rapid 80 GA device installation trunking in aluminium.



- Alu** Aluminium
- EL** Anodised

## Master data

Item number	6276973
Type	GA-E90130EL
Description 1	End piece
Manufacturer	OBO
Dimension	90x130x37
Colour	aluminium
Material	Aluminium
Surface	Anodised
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	14.5 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	1,5029 kg CO2e / 1 Piece

# Technical data sheet


End piece, for device installation trunking Rapid 80 type

GA-90130

Item number: 6276973



## Dimensions

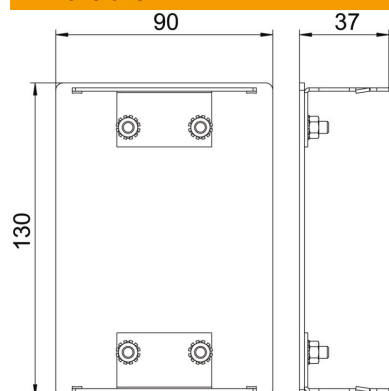

Length	37 mm
Width	130 mm
Height	90 mm

## Technical data

Version for	Symmetrical
Fastening type	Lockable
for duct width	130 mm
for trunking height	90 mm
Suitable for	Left/right
Halogen-free	yes
Cut lamination	no
Protection rating	IP30
Protective film	yes
Protection rating IK code	IK10
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-25 °C