

Technical data sheet

End piece, for device installation trunking Rapid 80 type
GA-90210
Item number: 6279673



End piece for tidy closure of the Rapid 80 GA device installation trunking in aluminium.



- Alu** Aluminium
- EL** Anodised

Master data


Item number	6279673
Type	GA-E90210EL
Description 1	End piece
Manufacturer	OBO
Dimension	90x210x37
Colour	aluminium
Material	Aluminium
Surface	Anodised
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	18.8 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	2,303 kg CO2e / 1 Piece

Technical data sheet

End piece, for device installation trunking Rapid 80 type
GA-90210
Item number: 6279673



Dimensions

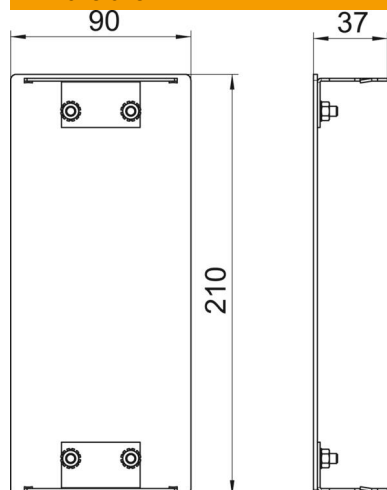

Length	37 mm
Width	210 mm
Height	90 mm

Technical data

Version for	Symmetrical
Fastening type	Lockable
for duct width	210 mm
for trunking height	90 mm
Suitable for	Left/right
Halogen-free	yes
Cut lamination	no
Protection rating	IP30
Protective film	yes
Protection rating IK code	IK10
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-25 °C