

Technical data sheet


Coupling GA-KUP90

Item number: 6279704



Joint connector for connecting the bases of Rapid 80 GA aluminium device installation trunking.

The scope of delivery of a coupling includes 2 connection plates.

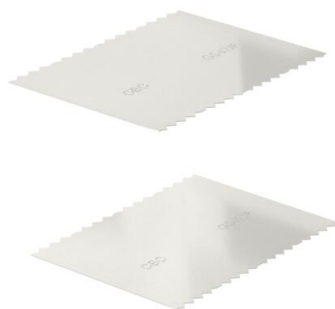

A2 Stainless steel

Master data

| | |
|------------------------------------|------------------------------|
| Item number | 6279704 |
| Type | GA-KUP90 |
| Description 1 | Coupling |
| Description 2 | univ., for trunking depth 90 |
| Manufacturer | OBO |
| Dimension | 84x120 |
| Colour | stainless steel |
| Material | Stainless steel 1.4301 |
| Smallest sales unit | 1 |
| Unit of quantity | Packaging unit |
| Weight | 8.2 kg |
| Weight unit | kg/100 PUs |
| CO2 Footprint (GWP) Cradle-to-Gate | 0,3805 kg CO2e / 2 Piece |


Technical data sheet

Coupling GA-KUP90

Item number: 6279704



Dimensions

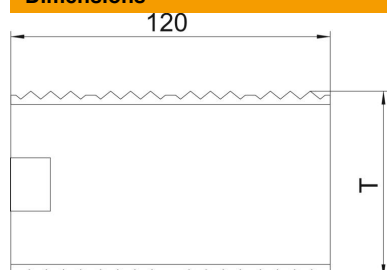

| | |
|--------|--------|
| Length | 120 mm |
| Width | 84 mm |

Technical data

| | |
|-----------------------------------|-----------|
| Version for | Universal |
| Type | coupling |
| Halogen-free | yes |
| Trunking depth | 90 mm |
| With equipotential bonding | yes |
| Protection rating | IP30 |
| Protection rating IK code | IK10 |
| Permitted temperature range, max. | 60 °C |
| Permitted temperature range, min. | -25 °C |