

# Technical data sheet

## Cover, for device installation trunking Rapid 45-2



Item number: 6112413



Trunking cover for closing the device installation trunking of the Rapid 45-2 GA... series. The 2-piece cover consists of a PVC base profile and an aluminium panel profile.

Note:

For anodised aluminium trunking, covers and fittings, light colour differences caused by permitted scatter due to the material and process conditions cannot be avoided (according to DIN 17 611). The 45 mm devices can be clicked in directly. When using PC/ABS hood fittings, there may be colour differences due to the different materials.



**Alu** Aluminium

**EL** Anodised

### Master data

Item number	6112413
Type	GA-OT45EL
Description 1	Cover
Description 2	Rapid 45-2, aluminium
Manufacturer	OBO
Dimension	45x2000
Colour	aluminium
Material	Aluminium
Surface	Anodised
Surface standard	
Smallest sales unit	2
Unit of quantity	Metre
Weight	47.45 kg
Weight unit	kg/100 m
CO2 Footprint (GWP) Cradle-to-Gate	3,7547 kg CO2e / 1 Meter


# Technical data sheet

Cover, for device installation trunking Rapid 45-2

Item number: 6112413



## Dimensions

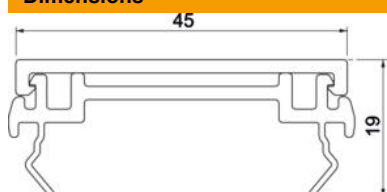

Length	2,000 mm
Width	45 mm
Height	19 mm

## Technical data

Version for	Smooth
Halogen-free	yes
Cover mounting type	Internal
Protection rating	IP40
Protective film	yes
Protection rating IK code	IK10
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-15 °C