

Technical data sheet

Aluminium external corner cover

Item number: 6279727



External corner cover for mounting on the Rapid 80 GA external corner fitting.



Alu Aluminium

EL Anodised

Master data

Item number	6279727
Type	GA-OTAEL
Description 1	Cover
Description 2	for external corner
Manufacturer	OBO
Dimension	12x76,5x300
Colour	aluminium
Material	Aluminium
Surface	Anodised
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	12.9 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	1,6841 kg CO2e / 1 Piece


Technical data sheet

Aluminium external corner cover

Item number: 6279727



Dimensions

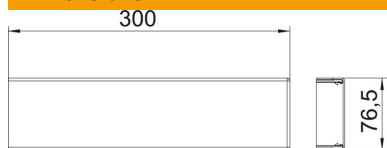

Length	300 mm
Width	76.5 mm
Height	12 mm



Technical data

Application	External corner
Halogen-free	yes
Cover mounting type	Internal
Protection rating	IP30
Protective film	yes
Protection rating IK code	IK10
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-25 °C