

Technical data sheet

Aluminium flat angle cover

Item number: 6279736



Flat angle cover for mounting on the Rapid 80 GA flat angle fitting.



Alu Aluminium

EL Anodised

Master data

| | |
|------------------------------------|--------------------------|
| Item number | 6279736 |
| Type | GA-OTFEL |
| Description 1 | Cover |
| Description 2 | for flat angle |
| Manufacturer | OBO |
| Dimension | 12x76,5x400 |
| Colour | aluminium |
| Material | Aluminium |
| Surface | Anodised |
| Surface standard | |
| Smallest sales unit | 1 |
| Unit of quantity | Piece |
| Weight | 28.6 kg |
| Weight unit | kg/100 pc. |
| CO2 Footprint (GWP) Cradle-to-Gate | 4,1961 kg CO2e / 1 Piece |


Technical data sheet

Aluminium flat angle cover

Item number: 6279736



Dimensions

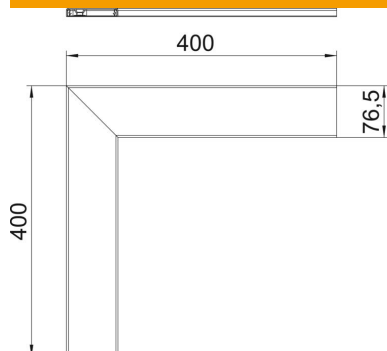

| | |
|--------|---------|
| Length | 400 mm |
| Width | 76.5 mm |
| Height | 12 mm |

Technical data

| | |
|-----------------------------------|----------|
| Version for | Smooth |
| Halogen-free | yes |
| Cover mounting type | Internal |
| Protection rating | IP30 |
| Protective film | yes |
| Protection rating IK code | IK10 |
| Permitted temperature range, max. | 60 °C |
| Permitted temperature range, min. | -25 °C |