

Technical data sheet

External corner, symmetrical, for device installation trunking Rapid 80 type GA-S70110

Item number: 6279213



External corner for changing the direction of the Rapid 80 GA aluminium device installation trunking.
The visible surfaces of the fittings are laminated. The cover must be ordered separately.



| | |
|-----|-----------|
| Alu | Aluminium |
| EL | Anodised |

Master data

| | |
|------------------------------------|---------------------------|
| Item number | 6279213 |
| Type | GA-SA70110EL |
| Description 1 | External corner |
| Description 2 | symmetrical |
| Manufacturer | OBO |
| Dimension | 70x110x300 |
| Colour | aluminium |
| Material | Aluminium |
| Surface | Anodised |
| Surface standard | |
| Smallest sales unit | 1 |
| Unit of quantity | Piece |
| Weight | 159.4 kg |
| Weight unit | kg/100 pc. |
| CO2 Footprint (GWP) Cradle-to-Gate | 20,4884 kg CO2e / 1 Piece |

Technical data sheet

External corner, symmetrical, for device installation trunking Rapid 80 type GA-S70110


Item number: 6279213



Dimensions



| | |
|--------|--------|
| Length | 300 mm |
| Width | 110 mm |
| Height | 70 mm |

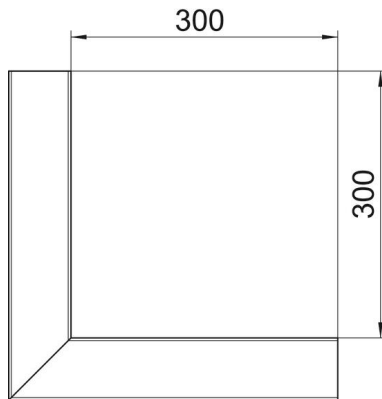

Technical data

| | |
|-----------------------------------|----------|
| Number of covers | 1 |
| Version for | Base |
| for duct width | 110 mm |
| for trunking height | 70 mm |
| Halogen-free | yes |
| Cable retaining clip | no |
| Duct connector | no |
| Cover mounting type | Internal |
| Mounting perforation in base | no |
| Cover width | 76.5 mm |
| Protection rating | IP30 |
| Protective film | yes |
| Protection rating IK code | IK10 |
| Symmetrical | yes |
| Permitted temperature range, max. | 60 °C |
| Permitted temperature range, min. | -25 °C |
| Angle range, min. | 90 mm |