

Technical data sheet

External corner, symmetrical, for device installation trunking Rapid 80 type GA-S70130

Item number: 6279310



External corner for changing the direction of the Rapid 80 GA aluminium device installation trunking.

The visible surfaces of the fittings are laminated. The cover must be ordered separately.



Alu Aluminium

Master data

| | |
|------------------------------------|---------------------------|
| Item number | 6279310 |
| Type | GA-SA70130RW |
| Description 1 | External corner |
| Description 2 | symmetrical |
| Manufacturer | OBO |
| Dimension | 70x130x300 |
| Colour | Pure white; RAL 9010 |
| Material | Aluminium |
| Smallest sales unit | 1 |
| Unit of quantity | Piece |
| Weight | 173.6 kg |
| Weight unit | kg/100 pc. |
| CO2 Footprint (GWP) Cradle-to-Gate | 22,9415 kg CO2e / 1 Piece |


Technical data sheet

External corner, symmetrical, for device installation trunking Rapid 80 type GA-S70130


Item number: 6279310



Dimensions

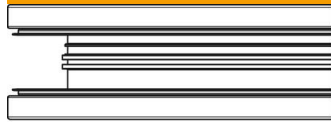

| | |
|--------|--------|
| Length | 300 mm |
| Width | 130 mm |
| Height | 70 mm |

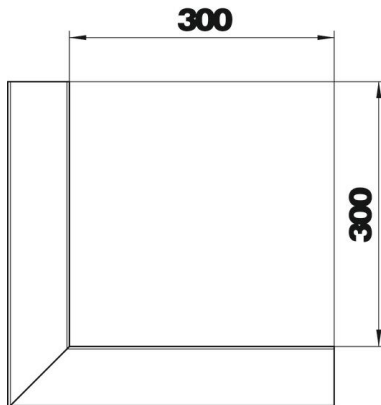

Technical data

| | |
|-----------------------------------|----------|
| Number of covers | 1 |
| Version for | Base |
| for duct width | 130 mm |
| for trunking height | 70 mm |
| Halogen-free | yes |
| Cable retaining clip | no |
| Duct connector | no |
| Cover mounting type | Internal |
| Mounting perforation in base | no |
| Cover width | 76.5 mm |
| Protection rating | IP30 |
| Protective film | yes |
| Protection rating IK code | IK10 |
| Symmetrical | yes |
| Permitted temperature range, max. | 60 °C |
| Permitted temperature range, min. | -25 °C |
| Angle range, min. | 90 mm |