

# Technical data sheet

Flat angle, symmetrical, for device installation trunking Rapid 80 type GA-S70110  
Item number: 6279223



Flat angle for changing the direction of the Rapid 80 GA aluminium device installation trunking.

The visible surfaces of the fittings are laminated. The cover must be ordered separately.



- Alu** Aluminium
- EL** Anodised

## Master data

Item number	6279223
Type	GA-SF70110EL
Description 1	Flat angle
Description 2	symmetrical
Manufacturer	OBO
Dimension	70x110x300
Colour	aluminium
Material	Aluminium
Surface	Anodised
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	126.6 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	17,5473 kg CO2e / 1 Piece


# Technical data sheet

Flat angle, symmetrical, for device installation trunking Rapid 80 type GA-S70110

Item number: 6279223



## Dimensions

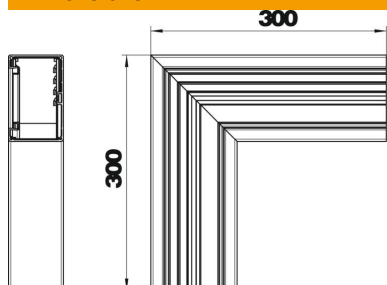

Length	300 mm
Width	110 mm
Height	70 mm

## Technical data

Number of covers	1
Version for	Base
for duct width	110 mm
for trunking height	70 mm
Halogen-free	yes
Cable retaining clip	no
Duct connector	no
Cover mounting type	Internal
Mounting perforation in base	no
Cover width	76.5 mm
Change of direction	Vertical, rising/falling
Protection rating	IP30
Protective film	yes
Protection rating IK code	IK10
Symmetrical	yes
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-25 °C
Angle range, min.	90 mm