

Technical data sheet

Flat angle, symmetrical, for device installation trunking Rapid 80 type GA-S70110
Item number: 6279220



Flat angle for changing the direction of the Rapid 80 GA aluminium device installation trunking.

The visible surfaces of the fittings are laminated. The cover must be ordered separately.



Alu Aluminium

Master data

Item number	6279220
Type	GA-SF70110RW
Description 1	Flat angle
Description 2	symmetrical
Manufacturer	OBO
Dimension	70x110x300
Colour	Pure white; RAL 9010
Material	Aluminium
Smallest sales unit	1
Unit of quantity	Piece
Weight	126.6 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	17,0751 kg CO2e / 1 Piece


Technical data sheet

Flat angle, symmetrical, for device installation trunking Rapid 80 type GA-S70110

Item number: 6279220



Dimensions

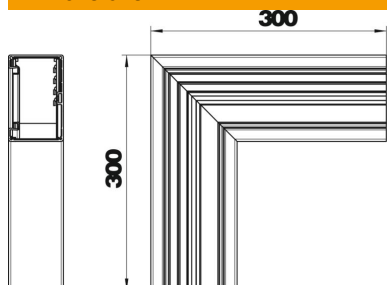

Length	300 mm
Width	110 mm
Height	70 mm

Technical data

Number of covers	1
Version for	Base
for duct width	110 mm
for trunking height	70 mm
Halogen-free	yes
Cable retaining clip	no
Duct connector	no
Cover mounting type	Internal
Mounting perforation in base	no
Cover width	76.5 mm
Change of direction	Vertical, rising/falling
Protection rating	IP30
Protective film	yes
Protection rating IK code	IK10
Symmetrical	yes
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-25 °C
Angle range, min.	90 mm