

# Technical data sheet

Flat angle, symmetrical, for device installation trunking Rapid 80 type GA-S70130  
Item number: 6279320



Flat angle for changing the direction of the Rapid 80 GA aluminium device installation trunking.

The visible surfaces of the fittings are laminated. The cover must be ordered separately.



Alu Aluminium

## Master data

Item number	6279320
Type	GA-SF70130RW
Description 1	Flat angle
Description 2	symmetrical
Manufacturer	OBO
Dimension	70x130x300
Colour	Pure white; RAL 9010
Material	Aluminium
Smallest sales unit	1
Unit of quantity	Piece
Weight	132.6 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	19,1405 kg CO2e / 1 Piece


# Technical data sheet

Flat angle, symmetrical, for device installation trunking Rapid 80 type GA-S70130

Item number: 6279320



## Dimensions

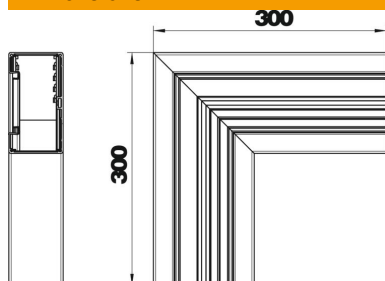

Length	300 mm
Width	130 mm
Height	70 mm

## Technical data

Number of covers	1
Version for for duct width	Base 130 mm
for trunking height	70 mm
Halogen-free	yes
Cable retaining clip	no
Duct connector	no
Cover mounting type	Internal
Mounting perforation in base	no
Cover width	76.5 mm
Change of direction	Vertical, rising/falling
Protection rating	IP30
Protective film	yes
Protection rating IK code	IK10
Symmetrical	yes
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-25 °C
Angle range, min.	90 mm