

# Technical data sheet

Internal corner, symmetrical, for device installation trunking Rapid 80 type GA-S70130

Item number: 6279343



Internal corner for changing the direction of the Rapid 80 GA aluminium device installation trunking.  
The visible surfaces of the fittings are laminated.



Alu Aluminium

EL Anodised

## Master data

Item number	6279343
Type	GA-SI70130EL
Description 1	Internal corner
Description 2	symmetrical
Manufacturer	OBO
Dimension	70x130x300
Colour	aluminium
Material	Aluminium
Surface	Anodised
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	148.8 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	20,5214 kg CO2e / 1 Piece


# Technical data sheet

Internal corner, symmetrical, for device installation trunking Rapid 80 type GA-S70130


Item number: 6279343



## Dimensions

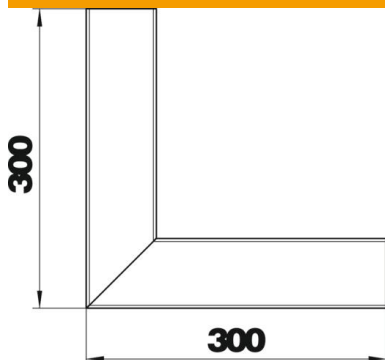

Length	300 mm
Width	130 mm
Height	70 mm

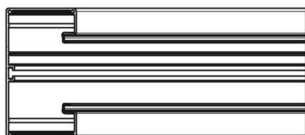

## Technical data

Number of covers	1
Version for	Base
Shape	Symmetrical
for duct dimension	70 x 130 mm
for duct width	130 mm
for trunking height	70 mm
Halogen-free	yes
Cable retaining clip	no
Duct connector	no
Cover mounting type	Internal
Mounting perforation in base	no
Cover width	76.5 mm
Protection rating	IP30
Protective film	yes
Protection rating IK code	IK10
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-25 °C
Angle range, min.	90 mm