

Technical data sheet

Internal corner, symmetrical, for device installation trunking Rapid 80 type GA-S90130

Item number: 6276943



Internal corner for changing the direction of the Rapid 80 GA aluminium device installation trunking.
The visible surfaces of the fittings are laminated.



Alu	Aluminium
EL	Anodised

Master data

Item number	6276943
Type	GA-SI90130EL
Description 1	Internal corner
Description 2	symmetrical
Manufacturer	OBO
Dimension	90x130x300
Colour	aluminium
Material	Aluminium
Surface	Anodised
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	163.8 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	22,3753 kg CO2e / 1 Piece


Technical data sheet

Internal corner, symmetrical, for device installation trunking Rapid 80 type GA-S90130

Item number: 6276943



Dimensions

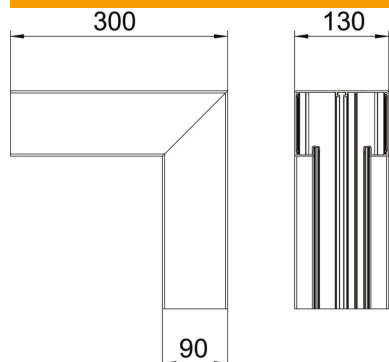

Length	300 mm
Width	130 mm
Height	90 mm

Technical data

Number of covers	1
Version for	Base
Shape	Symmetrical
for duct dimension	90 x 130 mm
for duct width	130 mm
for trunking height	90 mm
Halogen-free	yes
Cable retaining clip	no
Duct connector	no
Cover mounting type	Internal
Mounting perforation in base	no
Cover width	76.5 mm
Protection rating	IP30
Protective film	yes
Protection rating IK code	IK10
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-25 °C
Angle range, min.	90 mm