

Technical data sheet

T piece, symmetrical, for Rapid 80 device installation trunking, type GA-S70110

Item number: 6279260



T piece for branches of Rapid 80 GA aluminium device installation trunking. The visible surfaces of the fittings are laminated.



Alu Aluminium

Master data

Item number	6279260
Type	GA-ST70110RW
Description 1	T piece
Description 2	symmetrical
Manufacturer	OBO
Dimension	70x110x500
Colour	Pure white; RAL 9010
Material	Aluminium
Smallest sales unit	1
Unit of quantity	Piece
Weight	96.6 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	12,7849 kg CO2e / 1 Piece


Technical data sheet

T piece, symmetrical, for Rapid 80 device installation trunking, type GA-S70110

Item number: 6279260



Dimensions

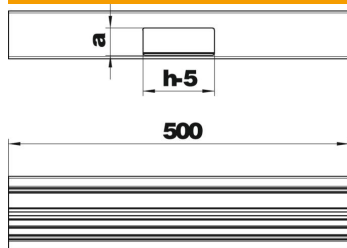

Length	500 mm
Width	110 mm
Height	70 mm

Technical data

Number of covers	1
Version for	Base
for duct width	110 mm
for trunking height	70 mm
Halogen-free	yes
Cable retaining clip	no
Duct connector	no
Cover mounting type	Internal
Mounting perforation in base	no
Cover width	76.5 mm
Protection rating	IP30
Protective film	yes
Protection rating IK code	IK10
Symmetrical	yes
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-25 °C