

Technical data sheet

T piece, symmetrical, for device installation trunking Rapid 80 type GA-S70130
Item number: 6279363



T piece for branches of Rapid 80 GA aluminium device installation trunking.
The visible surfaces of the fittings are laminated.



- Alu** Aluminium
- EL** Anodised

Master data


Item number	6279363
Type	GA-ST70130EL
Description 1	T piece
Description 2	symmetrical
Manufacturer	OBO
Dimension	70x130x500
Colour	aluminium
Material	Aluminium
Surface	Anodised
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	106.9 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	14,1747 kg CO2e / 1 Piece

Technical data sheet

T piece, symmetrical, for device installation trunking Rapid
80 type GA-S70130
Item number: 6279363



Dimensions

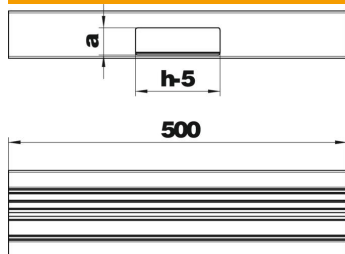

Length	500 mm
Width	130 mm
Height	70 mm

Technical data

Number of covers	1
Version for	Base
for duct width	130 mm
for trunking height	70 mm
Halogen-free	yes
Cable retaining clip	no
Duct connector	no
Cover mounting type	Internal
Mounting perforation in base	no
Cover width	76.5 mm
Protection rating	IP30
Protective film	yes
Protection rating IK code	IK10
Symmetrical	yes
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-25 °C