

# Technical data sheet

T piece, symmetrical, for device installation trunking Rapid 80 type GA-S90130  
Item number: 6276960



T piece for branches of Rapid 80 GA aluminium device installation trunking.  
The visible surfaces of the fittings are laminated.



Alu Aluminium

## Master data


Item number	6276960
Type	GA-ST90130RW
Description 1	T piece
Description 2	symmetrical
Manufacturer	OBO
Dimension	90x130x500
Colour	Pure white; RAL 9010
Material	Aluminium
Smallest sales unit	1
Unit of quantity	Piece
Weight	116.4 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	15,549 kg CO2e / 1 Piece

# Technical data sheet

T piece, symmetrical, for device installation trunking Rapid  
80 type GA-S90130  
Item number: 6276960



## Dimensions

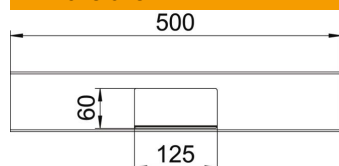

Length	500 mm
Width	130 mm
Height	90 mm



## Technical data

Number of covers	1
Version for	Base
for duct width	130 mm
for trunking height	90 mm
Halogen-free	yes
Cable retaining clip	no
Duct connector	no
Cover mounting type	Internal
Mounting perforation in base	no
Cover width	76.5 mm
Protection rating	IP30
Protective film	yes
Protection rating IK code	IK10
Symmetrical	yes
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-25 °C