

# Technical data sheet

GES2 with MT3 45

Item number: 7429580



Service outlet with all necessary system accessories for direct installation in screed floors for indoor use.

The scope of delivery contains a service outlet of nominal size 2 with universal fastening bracket and one module support for three Modul 45 devices.

Service outlet with carpet protection frame, hinged lid and cord outlet made of polyamide in the colour RAL 7011. 5 mm floor covering recess in the hinged lid.



PA Polyamide

## Master data

Item number	7429580
Type	GES2 KU 7011
Description 1	Service outlet construct. set
Description 2	for duct mounting
Manufacturer	OBO
Colour	Iron grey; RAL 7011
Material	Polyamide
Smallest sales unit	1
Unit of quantity	Piece
Weight	94.2 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	1,7907 kg CO2e / 1 Piece


# Technical data sheet

GES2 with MT3 45

Item number: 7429580



## Dimensions

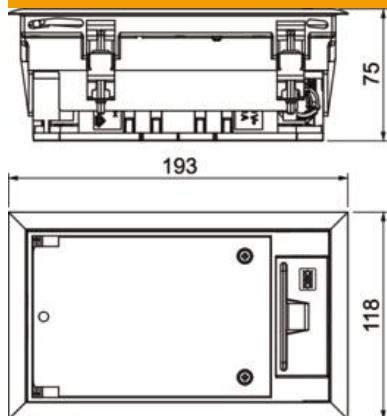

## Technical data

Cable outlet version	Swivellable cord outlet
Length of installation dimensions	181 mm
Protection rating (IP) when used	IP20
Protection rating (IP) when unused	IP40
Protection rating IK code	IK08
Clamping range D, max.	29 mm
Clamping range D, min.	7 mm
Opening mechanism	Handle
Floor covering thickness	5 mm