


Technical data sheet

GES9-3 service outlet with UT4 45

Item number: 7429592

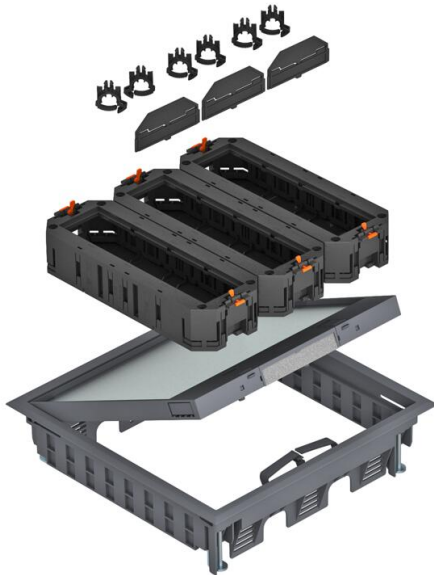

Service outlet with all necessary system accessories for direct installation in screed floors for indoor use.

The scope of delivery contains a service outlet of nominal size 9 with universal fastening bracket and three universal supports, each for 4 Modul 45® devices.

Service outlet with carpet protection frame, hinged lid and cord outlet made of polyamide in the colour RAL 7011. 10 mm floor covering recess in the hinged lid (changeable to 3, 5 or 8 mm).



PA Polyamide

Master data

Item number	7429592
Type	GES9-3 KU 7011
Description 1	Service outlet construct. set
Description 2	for universal mounting
Manufacturer	OBO
Colour	Iron grey; RAL 7011
Material	Polyamide
Smallest sales unit	1
Unit of quantity	Piece
Weight	230 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	7,8669 kg CO2e / 1 Piece


Technical data sheet

GES9-3 service outlet with UT4 45

Item number: 7429592



Dimensions

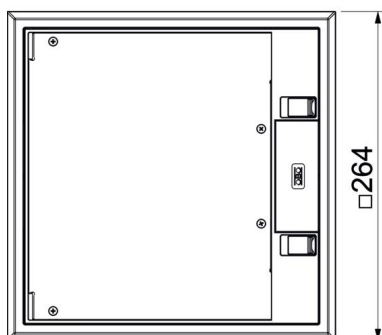

Technical data

Cable outlet version	Swivellable cord outlet
Length of installation dimensions	244 mm
Protection rating (IP) when used	IP20
Protection rating (IP) when unused	IP40
Protection rating IK code	IK08
Clamping range D, max.	76 mm
Clamping range D, min.	8 mm
Opening mechanism	Locking slider
Floor covering thickness	5 mm
Floor covering thickness max.	10 mm