

Technical data sheet

GES9/10 service trunking for OKA-T, 3-compartment

Item number: 7402292



Square flushfloor installation unit for mounting in an OKA-T trunking system. With mounting support to accept up to three APMT5 cover plates.
Service outlet with handle clamp for mounting in a OKA-T trunking system. With mounting support for receiving up to three APMT5 cover plates.



PA Polyamide

Master data

Item number	7402292
Type	GES9 10OK U 9011
Description 1	Service unit
Description 2	With univ. mounting for OKA/T
Manufacturer	OBO
Dimension	264x264x67
Colour	Graphite black; RAL 9011
Material	Polyamide
Smallest sales unit	1
Unit of quantity	Piece
Weight	211 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	5,6664 kg CO2e / 1 Piece


Technical data sheet

GES9/10 service trunking for OKA-T, 3-compartment



Item number: 7402292

Dimensions

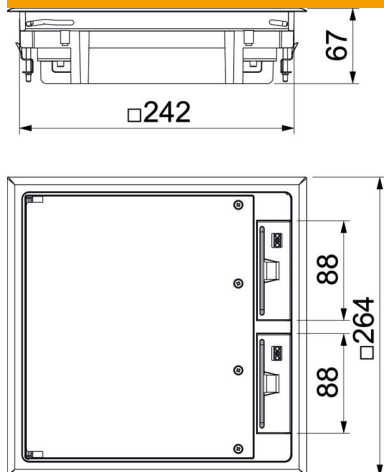

Technical data

Cable outlet version	Swivellable cord outlet
Seal installation option	no
Suitable for raised floor installation	yes
Suitable for screed-flush closed underfloor ducts	no
Suitable for cavity floor installation	yes
Suitable for wet care	no
Clamping range D, max.	36 mm
Clamping range D, min.	14 mm
Opening mechanism	Handle
Floor covering thickness	10 mm